


# ZB3180 | 9-pin D-sub connector (RS232/RS485) with switchable termination resistor




D-sub, plug, angled, 9-pin

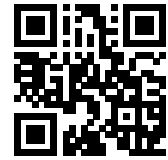

Mechanical data	
Installation size	D-sub
Connector type	plug
Configuration	angled
Number of positions (face)	9-pin
Body color	black
Body material	thermoplast
Max. cable outer diameter	8.5 mm
Environmental data	
Special features	The ZB3180 D-Sub connector is available as an accessory for wiring the RS232 and RS485 interfaces. The connector has two cable outlets and an active terminating resistor for the RS485 interface.
Ambient temperature (operation)	-25...+60 °C, -13...+140 °F
Protection rating	IP20

## Dimensions

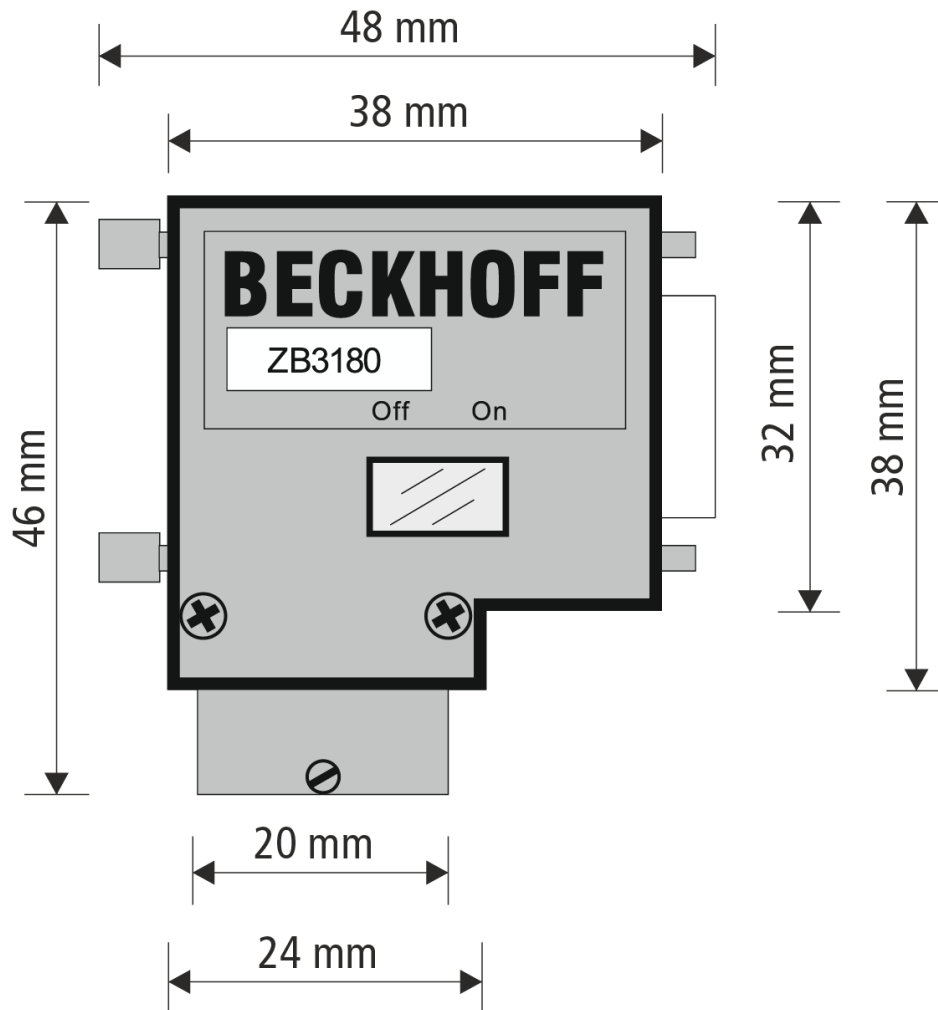

## Notes

- Illustrations similar

### Ordering information

ZB3180

9-pin D-sub connector for CX8x80/CX7080 (RS232/RS485) with switchable termination resistor

Beckhoff®, TwinCAT®, TwinCAT/BSD®, TC/BSD®, EtherCAT®, EtherCAT G®, EtherCAT G10®, EtherCAT P®, Safety over EtherCAT®, TwinSAFE®, XFC®, XTS® and XPlanar® are registered trademarks of and licensed by Beckhoff Automation GmbH. Other designations used in this publication may be trademarks whose use by third parties for their own purposes could violate the rights of the owners.

© Beckhoff Automation GmbH & Co. KG 02/2023

The information provided in this brochure contains merely general descriptions or characteristics of performance which in case of actual application do not always apply as described or which may change as a result of further development of the products. An obligation to provide the respective characteristics shall only exist if expressly agreed in the terms of contract.