




ZS7400-0001 | Plug, field assembly, EtherCAT P, IP 65/67, shielded

B40, plug, straight, male+male, pins 5+4, P-coded

Electrical data	
Rated voltage (Ethernet)	24 V DC
Rated current (Ethernet)	3 A at 40 °C
Rated voltage (power)	630 V AC / 850 V DC, 600V AC / DC (UL)
Rated current (power)	66 A at 50 °C
Rated impulse voltage (power)	6.0 kV
Rated impulse voltage (Ethernet)	1.0 kV
Shielding	yes
Contact resistance	< 10 mΩ (signal), < 5 mΩ (power)
Insulation resistance	≥ 100 MΩ (according to IEC 60512)
Mechanical data	
Installation size	B40
Connector type	plug
Configuration	straight
Contact type	male+male
Number of positions (face)	pins 5+4
Coding	P-coded
Wire termination	crimp connection
Mating cycles	≥ 100 (according to IEC 60512-9a)
Way of locking	bayonet
Body material	CuZn, Ni
Coupling nut material	GD-Zn, Ni
Seal	NBR
Contact carrier material	PA, UL 94 V-0
Contact carrier colour (Ethernet)	red
Contact carrier colour (power)	red
Contact material	CuZn, Ni b/Au 0.2 gal.
Max. wire cross section (power)	AWG5/16.0 mm ²
Max. wire cross section (Ethernet)	AWG22/0.34 mm ²
Max. cable outer diameter	23.0...26.0 mm
Environmental data	

Ambient temperature (operation)	-20...+90 °C, -4...+194 °F
Protection class	IP 65/67 in screwed condition (according to IEC 60529)
Pollution level	3/2 (according to IEC 60664-1)

Dimensions

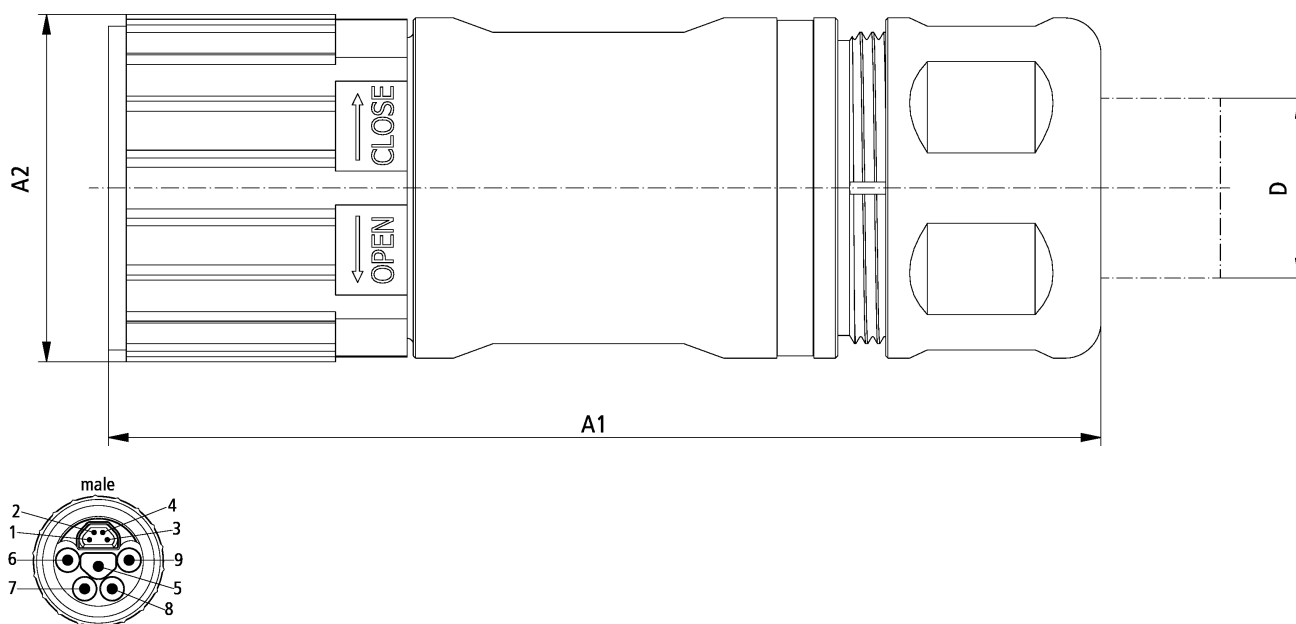

A1	115.0 mm
A2	Ø 47.0 mm

Notes

- Delivery without crimp contacts
- Illustrations similar

Ordering information	
ZS7400-0001	B40, plug, metal, shielded, crimp, straight, male+male, 5+4-pin, P-coded, IP 65/67

Accessories	
ZS7400-B004	B40 protection cap, plug, metal, IP 67, packaging unit = 5 pieces
ZS7400-B017	B40 colour coding for connector for field assembly, red, packaging unit = 10 pieces
ZS7400-B018	B40 colour coding for connector for field assembly, yellow, packaging unit = 10 pieces
ZS7400-B019	B40 colour coding for connector for field assembly, blue, packaging unit = 10 pieces
ZS7400-B020	B40 colour coding for connector for field assembly, green, packaging unit = 10 pieces
ZS7400-B021	B40 colour coding for connector for field assembly, orange, packaging unit = 10 pieces
ZS7400-B022	B40 colour coding for connector for field assembly, grey, packaging unit = 10 pieces
ZS7000-C001	Crimp contact, Ethernet element, male, AWG22/0.34 mm ² , PU = 50 pieces
ZS7000-C023	B40 crimp contact, male, 16 mm ² , packaging unit = 25 pieces

Beckhoff®, TwinCAT®, EtherCAT®, EtherCAT G®, EtherCAT G10®, EtherCAT P®, Safety over EtherCAT®, TwinSAFE®, XFC®, XT5® and XPlanar® are registered trademarks of and licensed by Beckhoff Automation GmbH. Other designations used in this publication may be trademarks whose use by third parties for their own purposes could violate the rights of the owners.

© Beckhoff Automation GmbH & Co. KG 05/2021

The information provided in this brochure contains merely general descriptions or characteristics of performance which in case of actual application do not always apply as described or which may change as a result of further development of the products. An obligation to provide the respective characteristics shall only exist if expressly agreed in the terms of contract.