

# ZS1000-2600 | Plug Y splitter for PROFIBUS, Modbus, RS485, IP67, shielded



M12, Y splitter, straight, male+female, 5-pin, B-coded




Electrical data	
Rated voltage	250 V
Shielding	yes
Contact resistance	< 5 mΩ
Insulation resistance	≥ 100 MΩ (according to IEC 60512)
Mechanical data	
Installation size	M12
Connector type	Y splitter
Configuration	straight
Contact type	male+female
Number of positions (face)	5-pin
Coding	B-coded
Mating cycles	≥ 100
Body material	plastic
Contact carrier material	plastic
Contact plating	Au
Contact material	CuZn

## Environmental data

Protection rating IP65/67 in screwed condition (according to IEC 60529)

## Dimensions

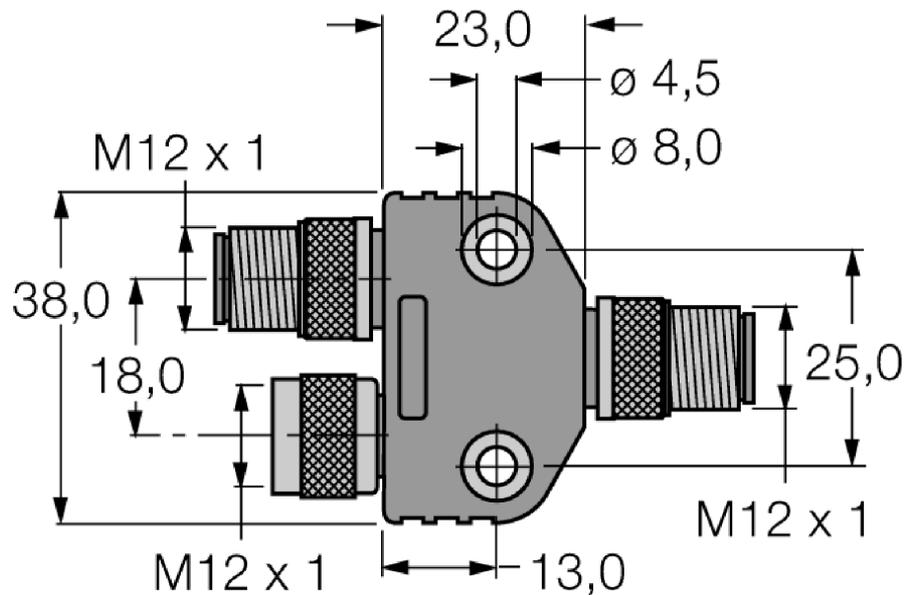

## Notes

- Illustrations similar

## Ordering information

ZS1000-2600

plug Y splitter for PROFIBUS, Modbus, RS485, IP67, M12, straight, male+female, 5-pin, B-coded, shielded

## Accessories

ZB8801-0000

torque wrench for hexagonal plugs, adjustable

ZB8801-0003

torque cable key, M12F/wrench size 18, for ZB8801-0000



Products marked with a crossed-out wheeled bin shall not be discarded with the normal waste stream. The device is considered as waste electrical and electronic equipment. The national regulations for the disposal of waste electrical and electronic equipment must be observed.

Beckhoff®, TwinCAT®, TwinCAT/BSD®, TC/BSD®, EtherCAT®, EtherCAT G®, EtherCAT G10®, EtherCAT P®, Safety over EtherCAT®, TwinSAFE®, XFC®, XTS® and XPlanar® are registered trademarks of and licensed by Beckhoff Automation GmbH. Other designations used in this publication may be trademarks whose use by third parties for their own purposes could violate the rights of the owners.

© Beckhoff Automation GmbH &amp; Co. KG 06/2023

The information provided in this brochure contains merely general descriptions or characteristics of performance which in case of actual application do not always apply as described or which may change as a result of further development of the products. An obligation to provide the respective characteristics shall only exist if expressly agreed in the terms of contract.